


DIN 127 A
Spring washers

Form A: bent open

Spring steel | bright | Cr(VI)-free

Further information: Norm has been withdrawn without replacement

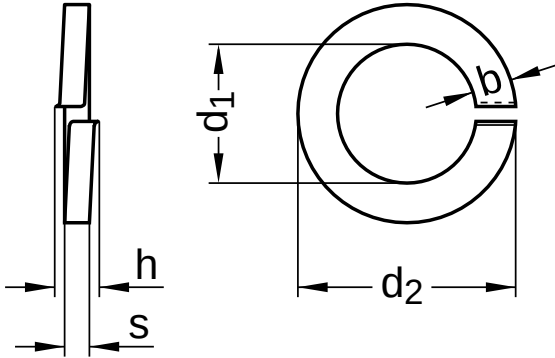

Diameter (d)	nominal size	b		d ₁		d ₂ max.	h		nominal size	s	
		min.	max.	min.	max.		min.	max.		min.	max.
2	0.9	0.80	1.00	2.1	2.4	4.4	–	–	0.5	0.40	0.60
2.5	1.0	0.90	1.10	2.6	2.9	5.1	–	–	0.6	0.50	0.70
3	1.3	1.20	1.40	3.1	3.4	6.2	1.9	2.1	0.8	0.70	0.90
3.5	1.3	1.20	1.40	3.6	3.9	6.7	1.9	2.2	0.8	0.70	0.90
4	1.5	1.40	1.60	4.1	4.4	7.6	2.1	2.5	0.9	0.80	1.00
5	1.8	1.70	1.90	5.1	5.4	9.2	2.7	3.2	1.2	1.10	1.30
6	2.5	2.35	2.65	6.1	6.5	11.8	3.6	4.2	1.6	1.50	1.70
8	3.0	2.85	3.15	8.1	8.5	14.8	4.6	5.4	2.0	1.90	2.10
10	3.5	3.30	3.70	10.2	10.7	18.1	5.0	5.9	2.2	2.05	2.35
12	4.0	3.80	4.20	12.2	12.7	21.1	5.8	6.8	2.5	2.35	2.65
14	4.5	4.30	4.70	14.2	14.7	24.1	6.8	8.0	3.0	2.85	3.15
16	5.0	4.80	5.20	16.2	17.0	27.4	7.8	9.2	3.5	3.30	3.70
20	6.0	5.80	6.20	20.2	21.2	33.6	8.8	10.4	4.0	3.80	4.20
22	6.0	5.80	6.20	22.5	23.5	35.9	8.8	10.4	4.0	3.80	4.20
24	7.0	6.75	7.25	24.5	25.5	40.0	11.0	13.0	5.0	4.80	5.20
27	7.0	6.75	7.25	27.5	28.5	43.0	11.0	13.0	5.0	4.80	5.20
30	8.0	7.75	8.25	30.5	31.7	48.2	13.6	16.1	6.0	5.80	6.20
36	10.0	9.75	10.25	36.5	37.7	58.2	13.6	16.1	6.0	5.80	6.20
39	10.0	9.75	10.25	39.5	40.7	61.2	13.6	16.1	6.0	5.80	6.20
42	12.0	11.75	12.25	42.5	43.7	68.2	15.6	18.4	7.0	6.75	7.25
45	12.0	11.75	12.25	45.5	46.7	71.2	15.6	18.4	7.0	6.75	7.25
48	12.0	11.75	12.25	49.0	50.5	75.0	15.6	18.4	7.0	6.75	7.25
52	14.0	13.75	14.25	53.0	54.5	83.0	18.0	21.2	8.0	7.75	8.25

All technical data refer to the measure mm

