


# HITSERT® 2

Brass | type 0931 | flange

**Advantages:**

- Ideal for thermoplastic parts
- Especially designed for thermal installation
- Screw-locked and low-tension anchoring
- High pull-out values
- Efficient installation due to single-spindle, multiple-spindle or automatic machines with preheating device

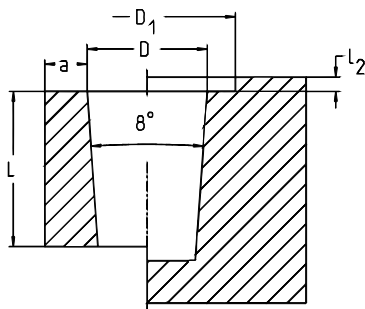

| Diameter (d) | Article number | d <sub>3</sub> nominal size | Length (l) nominal size | a min. | l <sub>2</sub> | D1   | Outer diameter (d2) | L min. |
|--------------|----------------|-----------------------------|-------------------------|--------|----------------|------|---------------------|--------|
| M 2.5        | 09311250056    | 6                           | 5.0                     | 1.5    | 0.6            | 6.2  | 4.1                 | 6.0    |
| M 3          | 09311030061    | 6                           | 5.5                     | 1.8    | 0.6            | 6.2  | 4.7                 | 6.5    |
| M 3.5        | 09311350068    | 7                           | 6.0                     | 1.8    | 0.8            | 7.2  | 5.5                 | 7.0    |
| M 4          | 09311040083    | 8                           | 7.5                     | 2.0    | 0.8            | 8.2  | 5.9                 | 8.5    |
| M 5          | 09311050010    | 8.5                         | 9.0                     | 2.5    | 1.0            | 8.7  | 7                   | 10.0   |
| M 6          | 09311060011    | 10                          | 10.0                    | 2.5    | 1.0            | 10.2 | 8.6                 | 11.0   |
| M 8          | 09311080013    | 12                          | 12.0                    | 3.0    | 1.0            | 12.2 | 11.1                | 13.0   |

All technical data refer to the measure mm

