

# RIVQUICK® Sealed type rivets

## Dome head

Note: stainless steel A2 body and stainless steel A2 mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d <sub>1</sub> nominal size	d <sub>2</sub> nominal size	Drilling diameter d nominal size	e	
					min.	max.
3.2	22143132080	3.2	6.5	3.3 - 3.4	1.0	3.0
	22143132095		6.5	3.3 - 3.4	3.0	5.0
	22143132120		6.5	3.3 - 3.4	5.0	6.5
4	22043140080	4	8.4	4.1	1.5	3.0
	22043140095		8.4	4.1	3.0	5.0
	22143140120		8	4.1 - 4.2	5.0	6.5
	22143140160		8	4.1 - 4.2	6.5	10.5
4.8	22043148095	4.8	10.1	4.9	3.0	5.0
	22143148120		9.5	4.9 - 5.0	5.0	6.5

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
3.2	8.0	0.9	2000	2200
	9.5	0.9	2000	2200
	12.0	0.9	2000	2200
4	8.0	1.7	3120	3560
	9.5	1.7	3120	3560
	12.0	1.5	3300	3400
	16.0	1.5	3300	3400
4.8	9.5	2.0	4000	4400
	12.0	1.5	4200	5200

All technical data refer to the measure mm



### Symbol list

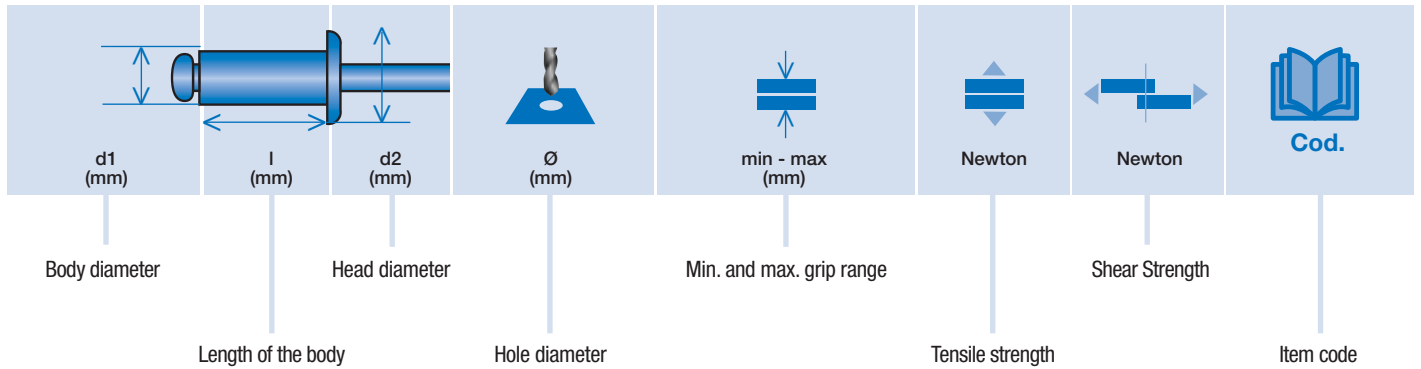

All technical data refer to the measure mm

