

RIVQUICK® Standard rivets

Dome head

Note: aluminium body and aluminium mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d ₁ nominal size	d ₂ nominal size	Drilling diameter d nominal size	e	
					min.	max.
3.2	22137132100	3.2	6.5	3.3 - 3.4	5.0	7.0
	22137132120				7.0	9.0
4	22137140060	4	8	4.1 - 4.2	1.0	2.5
	22137140080				3.0	4.5
	22137140100				5.0	6.5
	22137140140				8.0	10.5
	22137140160				10.0	13.0
	22137140200				13.5	16.0
4.8	22137148120	4.8	9.5	4.9 - 5.0	6.5	8.0
	22137148140				7.5	10.0
	22137148160				9.5	12.0
	22137148180				11.5	14.0

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
3.2	10	0.9	600	850
	12			
4	6	1.2	800	1200
	8			
	10			
	14			
	16			
4.8	20	1.4	1700	2100
	12			
	14			
	16			
	18			

All technical data refer to the measure mm



Symbol list

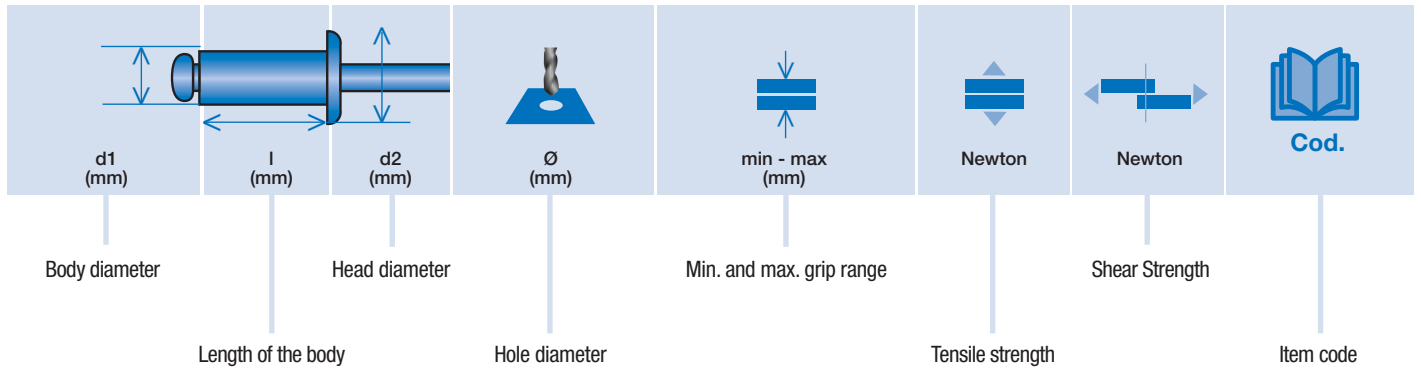

All technical data refer to the measure mm

