


DIN 479

Square head bolts

Square neck with half dog point

Steel 8.8 | bright | Cr(VI)-free | Metric thread

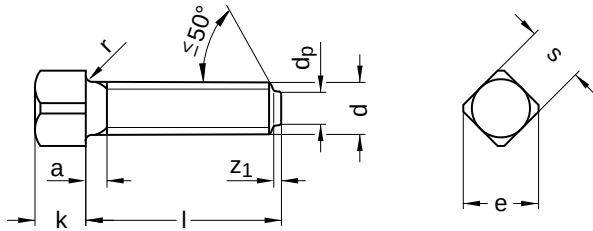

Diameter (d)	a nominal size	d _p		e		k			r	s		z ₁	Tool size
		min.	max.	max.	min.	nominal size	min.	max.		min.	max.		
M 6	3.00	3.82	4.0	8	7.42	6	5.85	6.15	0.25	5.82	6	1.5	SW 6
M 8	3.75	5.32	5.5	10	9.42	8	7.82	8.18	0.40	7.78	8	2	SW 8
M 10	4.50	6.78	7.0	13	12.30	10	9.82	10.18	0.40	9.78	10	2.5	SW 10
M 12	5.30	8.28	8.5	17	16.30	12	11.79	12.21	0.60	12.73	13	3	SW 13
M 16	6.00	11.73	12.0	21	20.16	16	15.79	16.21	0.60	15.73	16	4	SW 16

nominal size	Length (l)	
	min.	max.
16	15.65	16.35
20	19.58	20.42
25	24.58	25.42
30	29.58	30.42
35	34.50	35.50
40	39.50	40.50

nominal size	Length (l)	
	min.	max.
50	49.50	50.50
60	59.40	60.60

nominal size	Length (l)	
	min.	max.
70	69.40	70.60
80	79.40	80.60
100	99.30	100.70

Diameter (d)	Length (l)										
	16	20	25	30	35	40	50	60	70	80	100
M 6	●	●	●	●	●	●					
M 8		●	●	●	●	●	●				
M 10		●	●	●	●	●		●			
M 12			●	●	●	●		●	●	●	
M 16							●	●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

