

RIVQUICK® Varigrip multigrip blind rivets

Dome head

Note: steel body and steel mandrel

Technical information can be found on the last page.




Diameter (d)	d ₁ nominal size	d ₂ nominal size	Drilling diameter d nominal size	e		Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
				min.	max.				
3.2	3.2	7.6	3.3 - 3.4	1.0	7.0	12	1.1	1000	1400
4	4	8.4	4.1 - 4.2	2.0	8.0	13	1.5	1500	2000
4.8	4.8	10.1	4.9 - 5.0	1.5	6.3	11	1.6	2700	2900

All technical data refer to the measure mm



Symbol list

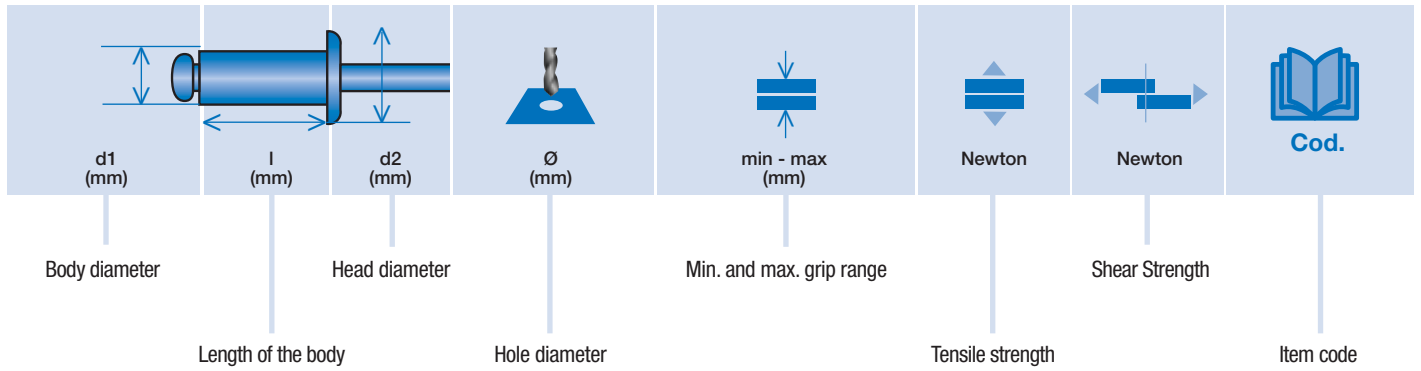

All technical data refer to the measure mm

