


SNAPLOC® Ball studs

Self-tapping external thread

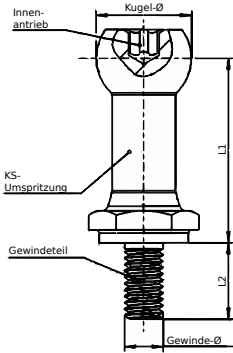

Article number	Outer dimension	Depth (L1)	Colour	Thread dimensions	Thread length (L2)	Ball diameter (D)
40300070027	SW 10	11.9	black	6	13.7	7
40300100019	SW 13	16.0	black	6	13.7	10
40300100039	SW 13	20.3	black	6	13.7	10
40300803902	SW 10	9.9	black	6	13.7	8
40321503904	SW 15	18.0	black	ST 6.3	30.0	15
40390070032	SW 8	22.0	black	ST 4.2	13.0	7
40390080048	SW 13	20.0	black	5	20.0	8
40390190601	SW 15	61.0	black	6	13.7	15

All technical data refer to the measure mm

